


Mechanical data

Mounting part	Mounting clamps
Null point	73.0 mm

Range/Distance

Non-linearity max.	±100 µm
Repeat accuracy	≤ 0.1 mV
Repeatability	≤4 µm
Resolution	≤ 2 µm
Sampling rate, length-dependent	1 kHz, standard

Connector Drawings

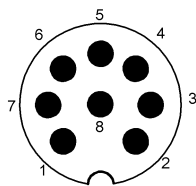

Wiring Diagrams (Schematic)

Pin	
1	GND output
2	GND output
3	10...0 V
4	NC
5	0...10 V
6	GND
7	+24 V DC
8	NC