


Mechanical data

Mounting part	Mounting clamps
Null point	73.0 mm

Range/Distance

Non-linearity max.	±0.02 % FS
Repeat accuracy	≤ ± 0.2 µA
Repeatability	≤4 µm
Resolution	≤ 0.2 µA
Sampling rate, length-dependent	1 kHz, standard

Connector Drawings

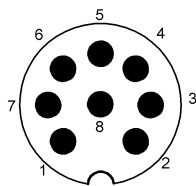

Wiring Diagrams (Schematic)

Pin	
1	NC
2	GND output
3	NC
4	NC
5	4...20 mA
6	GND
7	+24 V DC
8	NC