



## Interface

Cycle time min.	2.5 ms
Digital inputs	16x PNP, Type 2
IO-Link version	1
Interface	IO-Link 1.0
Process data IN	2 bytes
Process data cycle min.	2.5 ms
Transfer rate	COM2 (38.4 kBaud)

## Material

Gasket, material	FKM 75
Housing material	PBT, GF
Housing shield	no


## Mechanical data

Dimension	30 x 24 x 129.5 mm
Mounting part	2-hole screw mount
Weight	169 g

## Remarks

See short guide

## Connector Drawings

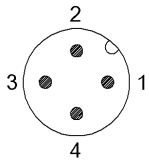


IO-Link

PIN 1: +24V

PIN 2: not used

PIN 3: GND, reference potential

 PIN 4: IO-Link



Input Ports

PIN 1: +24V

PIN 2: Input

PIN 3: 0V

PIN 4: Input