

CE  US LISTED EAC 

1 / 2

Material

Cover material	Aluminium, Die-cast, nickel plated
Housing material	Aluminium, Anodized
Housing material, surface protection	Anodized


Mechanical data

Mounting part	Mounting clamps
Null point	73.0 mm
Overall Length	2446 mm

Range/Distance

Measuring length	2300 mm
Non-linearity max.	±0.02 % FS
Repeat accuracy	≤ 0.1 mV
Repeatability	≤4 µm
Resolution	≤ 0.1 mV
Sampling rate, length-dependent	1 kHz, standard

Connector Drawings

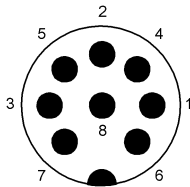

Wiring Diagrams (Schematic)

Pin	
1	NC
2	GND output
3	10...0 V
4	NC
5	0...10 V
6	GND
7	+24 V DC
8	NC